

Part No: 811-025F

Fabricated Fittings

Elbow

Desc: 2-1/2 PVC 11-1/4 ELL SOC SCH80

MSRP: 65.67

Part Code: 083

Weight(lbs): 0.922


Weight(kg): 0.418

Weight(gm): 418

Size: 2-1/2"

Color: GRAY

Material: PVC

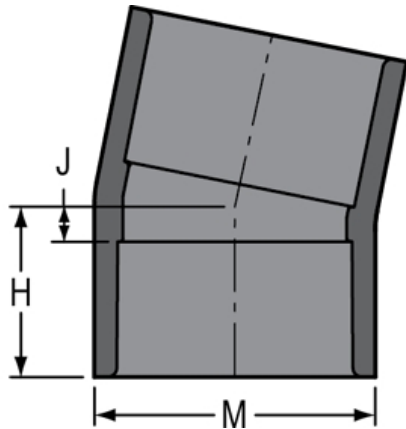

H = 2-11/16

J = 11/16

M = 3-7/16

Schedule SCH 80

Angle 11-1/4 Degree

Connection Socket X Socket

Type Standard

Fabricated Dimension References:

- G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.
- H** = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.
- J** = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.
- L** = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.
- M** = Outside diameter of socket/thread hub; $\pm 1/4$ inch.
- N** = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.
- W** = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

