

Part No: 811-100CF

Fabricated Fittings

Elbow

Desc: 10 CPVC 11-1/4 ELL SOC SCH80 FAB

MSRP: 1655.9

Part Code: 097

Weight(lbs): 15.829


Weight(kg): 7.18

Weight(gm): 7180

Size: 10"

Color: GRAY

Material: CPVC

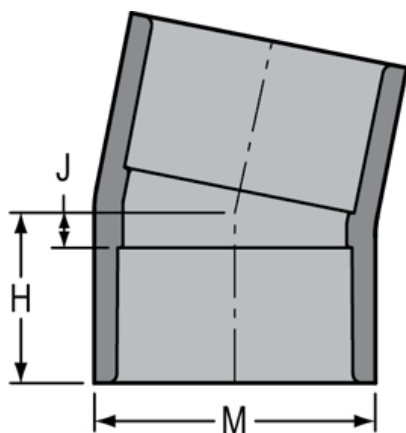

H = 6-11/16

J = 1-7/16

M = 11-15/16

Schedule SCH 80

Angle 11-1/4 Degree

Connection Socket X Socket

Type Standard

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

