

Part No: 812-002

Schedule 80 PVC & CPVC

Elbow

Desc: 1/4 PVC 90 ST ELL MPTXFPT SCH80

MSRP: 29.62

Part Code: 080

Weight(lbs): 0.024


Weight(kg): 0.011

Weight(gm): 11

Size: 1/4"

Color: GRAY

Material: PVC

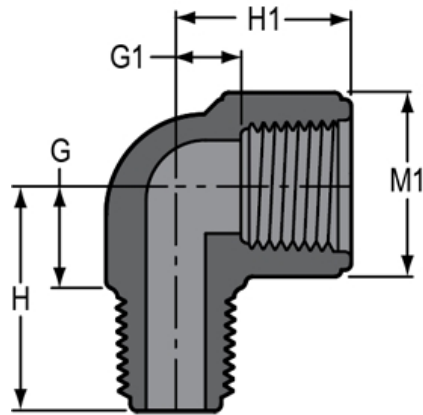

Connection Mipt x Fipt

Angle 90°

Type Standard

M1 = 13/16

G1 = 1/4

H = 1-1/16

H1 = 27/32

G = 9/16

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

