

Part No: 812-012

Schedule 80 PVC & CPVC

Elbow

Desc: 1-1/4 PVC 90 ST ELL MPTXFPT SCH80

MSRP: 43.62

Part Code: 080

Weight(lbs): 0.399


Weight(kg): 0.181

Weight(gm): 181

Size: 1-1/4"

Color: GRAY

Material: PVC

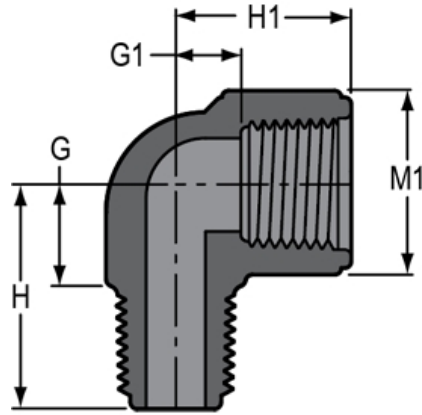

Connection Mipt x Fipt

Angle 90°

Type Standard

G = 2-9/16

G1 = 15/16

H = 3-5/16

H1 = 1-31/32

M1 = 2-7/32

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

