

Part No: 812-015

Schedule 80 PVC & CPVC

Elbow

Desc: 1-1/2 PVC 90 ST ELL MPTXFPT SCH80

MSRP: 71.47

Part Code: 080

Weight(lbs): 0.538


Weight(kg): 0.244

Weight(gm): 244

Size: 1-1/2"

Color: GRAY

Material: PVC

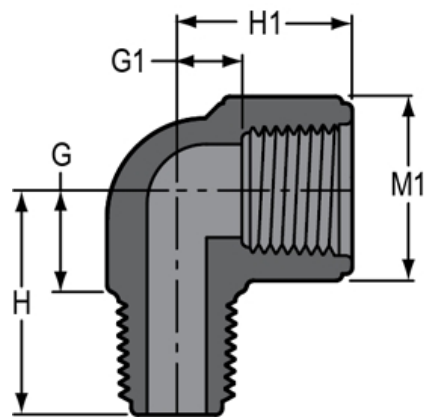

Connection Mipt x Fipt

Angle 90°

Type Standard

G = 2-11/16

G1 = 1-3/16

H = 3-7/16

H1 = 2-1/8

M1 = 2-3/8

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Bushing Dimension References

