

Part No: 816-015F

Fabricated Fittings

Elbow

Desc: 1-1/2 PVC 22-1/2 ELL SOC SCH80 FAB

MSRP: 47.4

Part Code: 083

Weight(lbs): 0.291


Weight(kg): 0.132

Weight(gm): 132

Size: 1-1/2"

Color: GRAY

Material: PVC

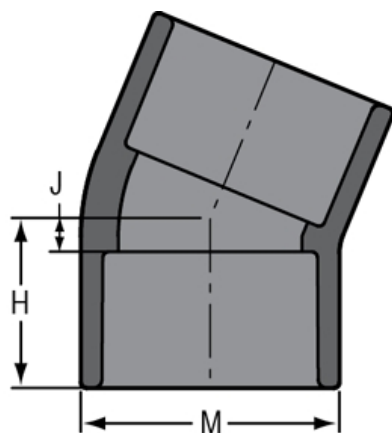

H = 2- 1/8

J = 5/8

M = 2- 5/16

Schedule SCH 80

Angle 22-1/2 Degree

Connection Socket X Socket

Type Standard

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

