

Part No: 817-002

Schedule 80 PVC & CPVC

Elbow

Desc: 1/4 PVC 45 ELL SOC SCH80

MSRP: 19.93

Part Code: 080

Weight(lbs): 0.026

Weight(kg): 0.012

Weight(gm): 12

Size: 1/4"


Color: GRAY

Material: PVC

Connection Socket x Socket

Angle 45°

Type Standard

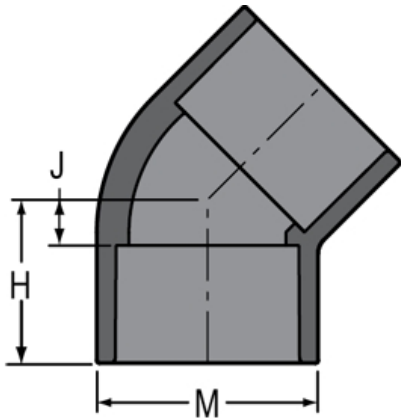

H = 13/16

J = 5/32

M = 27/32

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

