

Part No: 817-015BL

Low Extractable

Elbow

Desc: 1-1/2 PVC LE 45 ELL SOC SCH80

MSRP: 38.3

Part Code: 065

Weight(lbs): 0.295

Weight(kg): 0.134

Weight(gm): 134


Size: 1-1/2"

Color: BLUE

Material: PVC LE

Connection Socket x Socket

Type 45° Elbow

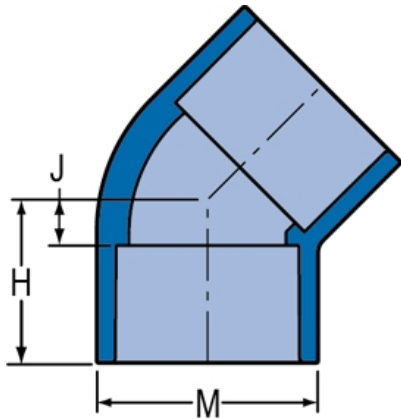

H = 1-27/32

J = 7/16

M = 2-3/8

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

