

Part No: 817-040BL

Low Extractable

Elbow

Desc: 4 PVC LE 45 ELL SOC SCH80

MSRP: 331.99

Part Code: 065

Weight(lbs): 2.24

Weight(kg): 1.016

Weight(gm): 1016


Size: 4"

Color: BLUE

Material: PVC LE

Connection Socket x Socket

Type 45° Elbow

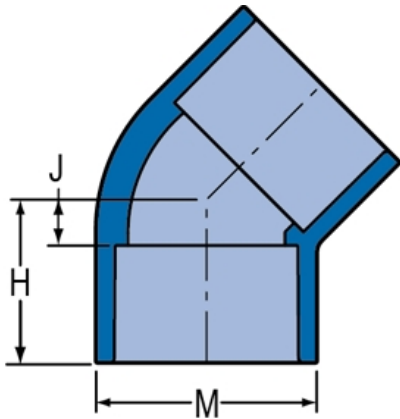

H = 3-3/8

J = 1-3/32

M = 5-1/4

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

