

Part No: 817-140C

Schedule 80 PVC & CPVC

Elbow

Desc: 14 CPVC 45 ELL SOC SCH80

MSRP: 5543.51

Part Code: 095

Weight(lbs): 43.039

Weight(kg): 19.522

Weight(gm): 19522

Size: 14


Color: GRAY

Material: CPVC

Connection Socket x Socket

Angle 45°

Type Standard

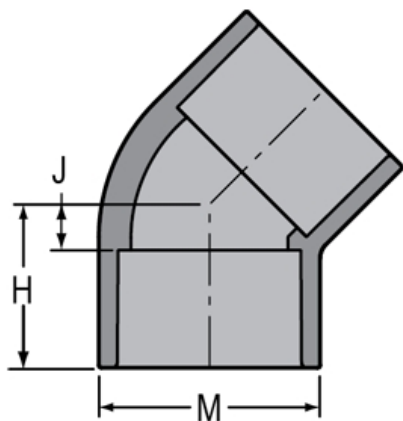

H = 10-11/32

J = 3- 5/16

M = 15- 5/8

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

