

**Part No:** 8170-060C

**Schedule 80 PVC & CPVC**

**Tank Adapter**

**Desc:** 6 CPVC TANK ADAPTER SOCXSOC NPRN GASKET

**MSRP:** 1703.68

**Part Code:** 101

**Weight(lbs):** 5.772

**Weight(kg):** 2.618

**Weight(gm):** 2618


**Size:** 6

**Color:** GRAY

**Material:** CPVC

**Connection** Socket x Socket (New Style)

**Gasket** Neoprene

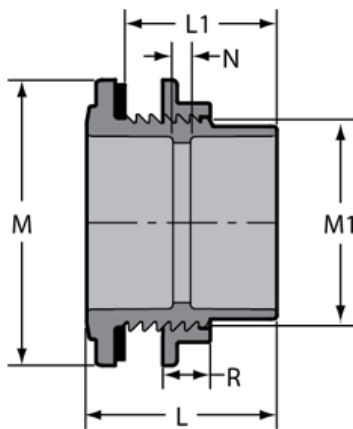

$R = 1-1/4$

**Min Hole Size** = 8

$L = 5$

$L1 = 4$

$M = 10-3/32$

$M1 = 8$

$N = 1/8$

## Injection Molded Dimension References:

**G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses;  $\pm 1/32$  inch.

**H** = Intersection of center lines to face of fitting; 90° elbows tees, crosses;  $\pm 1/32$  inch.

**J** = Intersection of center lines to bottom of socket/thread; 45° elbows;  $\pm 1/32$  inch

**L** = Overall length of fittings;  $\pm 1/16$  inch.

**M** = Outside diameter of socket/thread hub;  $\pm 1/16$  inch.

**N** = Socket bottom to socket bottom; couplings;  $\pm 1/16$  inch.

**W** = Height of cap;  $\pm 1/16$  inch

## Typical Molded Dimension References

