

Part No: 8170E-080C

Schedule 80 PVC & CPVC

Tank Adapter

Desc: 8 CPVC TANK ADAPTER SOCXSOC EPDM GASKET

MSRP: 3896.34

Part Code: 101

Weight(lbs): 16.87

Weight(kg): 7.652

Weight(gm): 7652


Size: 8"

Color: GRAY

Material: CPVC

Connection Socket x Socket (New Style)

Gasket EPDM

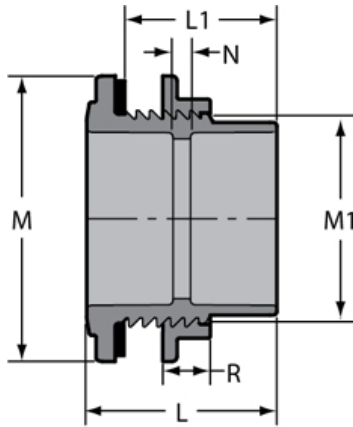

L = 8-19/32

L1 = 6-7/8

M = 12-15/16

M1 = 10-7/32

N = 1/2

R = 1- 1/2

Min Hole Size = 10-3/8

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

