

Part No: 8170V-010C

Schedule 80 PVC & CPVC

Tank Adapter

Desc: 1 CPVC TANK ADAPTER SOCXSOC FKM GASKET

MSRP: 161.2

Part Code: 101

Weight(lbs): 0.39

Weight(kg): 0.177

Weight(gm): 177


Size: 1"

Color: GRAY

Material: CPVC

Connection Socket x Socket (New Style)

Gasket FKM

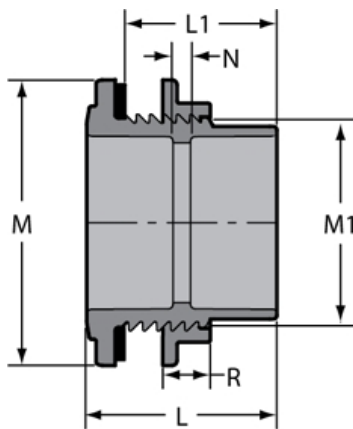

L = 3-9/32

L1 = 2-9/16

M = 2-21/32

M1 = 1-31/32

N = 1

R = 5/8

Min Hole Size = 2

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

