

Part No: 8170V-012BL

Low Extractable

Tank Adapters

Desc: 1-1/4 PVC LE TANK ADAPT SOCXSOC FKM GSK

MSRP: 150.69

Part Code: 065

Weight(lbs): 0.47


Weight(kg): 0.213

Weight(gm): 213

Size: 1-1/4"

Color: BLUE

Material: PVC LE

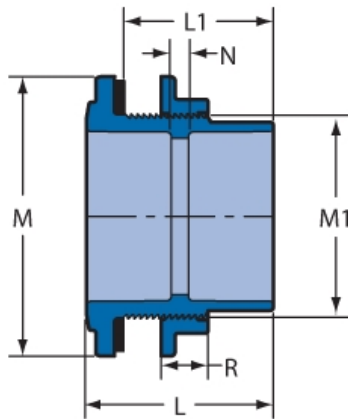

Type Tank Adapter
Connection Socket x Socket
Gasket FKM

L = 3-13/32

Hole Size = 2-3/8
(in.)

L1 = 2-5/8

M = 3-1/8

M1 = 2-5/16

N = 29/32

R = 5/8

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

