

Part No: 8171-002C

Schedule 80 PVC & CPVC

Tank Adapter

Desc: 1/4 CPVC TANK ADAPTER SOCXFPT NPRN GASKT

MSRP: 81.18

Part Code: 101

Weight(lbs): 0.121

Weight(kg): 0.055

Weight(gm): 55


Size: 1/4"

Color: GRAY

Material: CPVC

Connection Socket x Fipt (New Style)

Gasket Neoprene

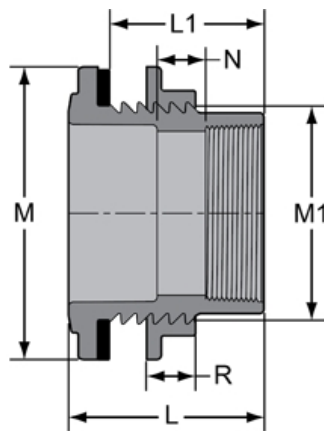

L = 2-15/32

L1 = 1-13/16

M = 1-17/32

M1 = 1-1/32

N = 1- 1/4

R = 1/2

Min Hole Size = 1-1/16

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

