

Part No: 8171-007

Schedule 80 PVC & CPVC

Tank Adapter

Desc: 3/4 PVC TANK ADAPTER SOCXFPT NPRN GASKET

MSRP: 65.74

Part Code: 100

Weight(lbs): 0.247

Weight(kg): 0.112

Weight(gm): 112


Size: 3/4"

Color: GRAY

Material: PVC

Connection Socket x Fipt (New Style)

Gasket Neoprene

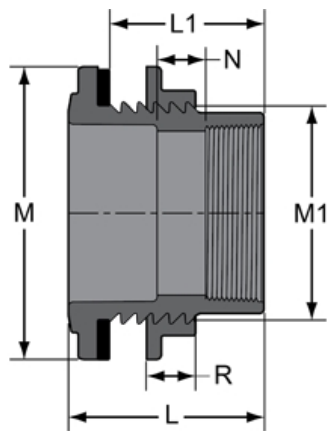

L = 2-15/16

L1 = 2-3/16

M = 2- 1/4

M1 = 1- 5/8

N = 1- 3/16

R = 5/8

Min Hole Size = 1-3/4

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

