

Part No: 8171-015CSR

Schedule 80 PVC & CPVC

Tank Adapter

Desc: 1-1/2 CPVC TANK ADPT SOCXSRFPT NPRN GSKT

MSRP: 163.98

Part Code: 101

Weight(lbs): 0.747

Weight(kg): 0.339

Weight(gm): 339


Size: 1-1/2"

Color: GRAY

Material: CPVC

Connection Socket x SR Fipt (New Style)

Gasket Neoprene

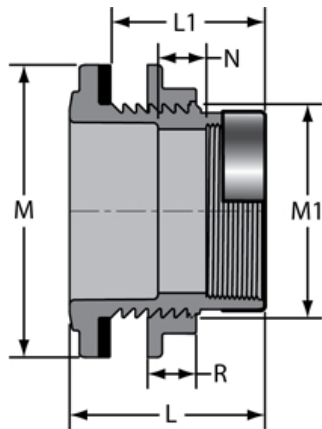

L = 3- 5/8

L1 = 2-13/16

M = 3- 5/8

M1 = 2-11/16

N = 1- 1/4

R = 5/8

**Min Hole
Size** = 2-3/4

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

