

Part No: 8171-020CSR

Schedule 80 PVC & CPVC

Tank Adapter

Desc: 2 CPVC TANK ADPTER SOCXSRFPT NPRN GASKET

MSRP: 226.76

Part Code: 101

Weight(lbs): 1.362

Weight(kg): 0.618

Weight(gm): 618


Size: 2"

Color: GRAY

Material: CPVC

Connection Socket x SR Fipt (New Style)

Gasket Neoprene

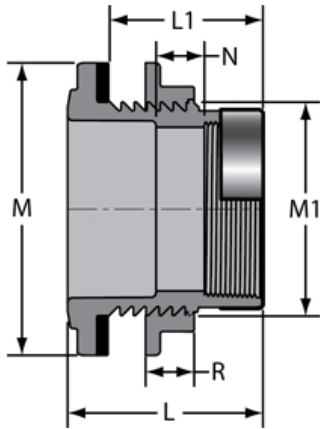

L = 4- 1/8

L1 = 3- 1/4

M = 4- 7/8

M1 = 3- 1/4

N = 1- 5/8

R = 3/4

Min Hole Size = 3-3/8

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

