

Part No: 8171-040C

Schedule 80 PVC & CPVC

Tank Adapter

Desc: 4 CPVC TANK ADAPTER SOCXFPT NPRN GASKET

MSRP: 619.51

Part Code: 101

Weight(lbs): 3.36

Weight(kg): 1.524

Weight(gm): 1524


Size: 4"

Color: GRAY

Material: CPVC

Connection Socket x Fipt (New Style)

Gasket Neoprene

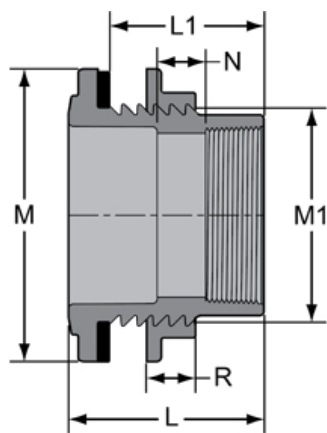

L = 4-31/32

L1 = 3-15/16

M = 7-7/16

M1 = 5-7/16

N = 1-7/32

R = 1- 1/4

Min Hole Size = 5-1/2

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

