

Part No: 8171E-003CSR

Schedule 80 PVC & CPVC

Tank Adapter

Desc: 3/8 CPVC TANK ADAPT SOCXSRFPT EPDM GASKT

MSRP: 94.79

Part Code: 101

Weight(lbs): 0.141

Weight(kg): 0.064

Weight(gm): 64


Size: 3/8"

Color: GRAY

Material: CPVC

Connection Socket x SR Fipt (New Style)

Gasket EPDM

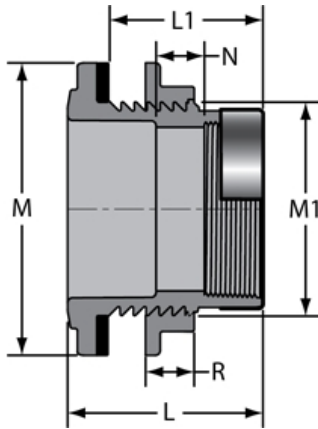

L = 2- 1/2

L1 = 1-13/16

M = 1- 5/8

M1 = 1- 3/16

N = 1- 3/16

R = 1/2

**Min Hole
Size** = 1-3/16

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

