

Part No: 8171E-010CSR

Schedule 80 PVC & CPVC

Tank Adapter

Desc: 1 CPVC TANK ADPTER SOCXSRFPT EPDM GASKET

MSRP: 128.1

Part Code: 101

Weight(lbs): 0.417

Weight(kg): 0.189

Weight(gm): 189


Size: 1"

Color: GRAY

Material: CPVC

Connection Socket x SR Fipt (New Style)

Gasket EPDM

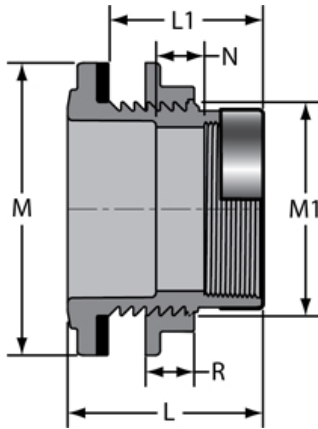

L = 3- 5/16

L1 = 2-13/16

M = 2- 5/8

M1 = 1-31/32

N = 1- 1/4

R = 5/8

**Min Hole
Size** = 2

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

