

Part No: 8171E-025CSR

Schedule 80 PVC & CPVC

Tank Adapter

Desc: 2-1/2 CPVC TANK ADAPT SOCXSRFPT EPDM GSK

MSRP: 359.8

Part Code: 101

Weight(lbs): 2.101

Weight(kg): 0.953

Weight(gm): 953


Size: 2-1/2"

Color: GRAY

Material: CPVC

Connection Socket x SR Fipt (New Style)

Gasket EPDM

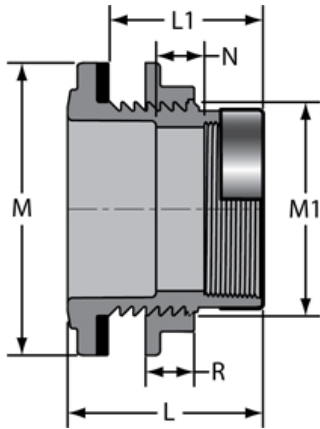

L = 4- 7/8

L1 = 3- 7/8

M = 5- 1/4

M1 = 3-13/16

N = 1-11/16

R = 1

**Min Hole
Size** = 3-7/8

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

