

**Part No:** 8171V-012CSR

**Schedule 80 PVC & CPVC**

**Tank Adapter**

**Desc:** 1-1/4 CPVC TANK ADPT SOCXSRFPT FKM GASKT

**MSRP:** 205.89

**Part Code:** 101

**Weight(lbs):** 0.558

**Weight(kg):** 0.253

**Weight(gm):** 253


**Size:** 1-1/4"

**Color:** GRAY

**Material:** CPVC

**Connection** Socket x SR Fipt (New Style)

**Gasket** FKM

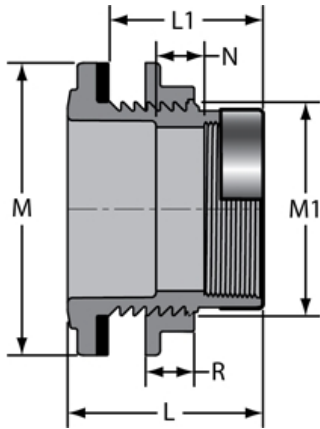

**L** = 3-13/32

**L1** = 2- 5/8

**M** = 3- 3/32

**M1** = 2- 5/16

**N** = 1-17/32

**Min Hole Size** = 2-3/8

**R** = 5/8

## Injection Molded Dimension References:

**G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

**H** = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

**J** = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

**L** = Overall length of fittings; ± 1/16 inch.

**M** = Outside diameter of socket/thread hub; ± 1/16 inch.

**N** = Socket bottom to socket bottom; couplings; ± 1/16 inch.

**W** = Height of cap; ± 1/16 inch

## Typical Molded Dimension References

