

Part No: 8171V-015SR

Schedule 80 PVC & CPVC

Tank Adapter

Desc: 1-1/2 PVC TANK ADPT SOCXSRFPT FKM GASKET

MSRP: 171.44

Part Code: 100

Weight(lbs): 0.723

Weight(kg): 0.328

Weight(gm): 328


Size: 1-1/2"

Color: GRAY

Material: PVC

Connection Socket x SR Fipt (New Style)

Gasket FKM

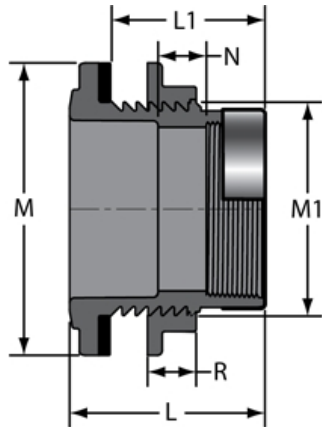

L = 3- 5/8

Min Hole Size = 2-3/4

L1 = 2-13/16

M = 3- 5/8

M1 = 2-11/16

N = 1-9/32

R = 5/8

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

