

Part No: 8171V-030CSR

Schedule 80 PVC & CPVC

Tank Adapter

Desc: 3 CPVC TANK ADAPTER SOCXSRFPT FKM GSKT

MSRP: 574.47

Part Code: 101

Weight(lbs): 2.899

Weight(kg): 1.315

Weight(gm): 1315


Size: 3"

Color: GRAY

Material: CPVC

Connection Socket x SR Fipt (New Style)

Gasket FKM

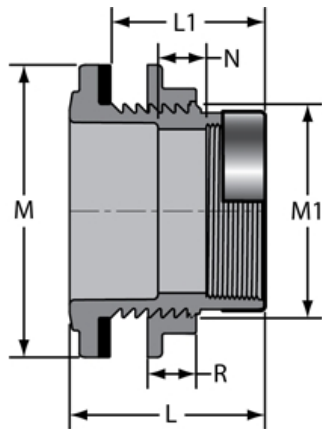

L = 5- 1/2

L1 = 4- 1/2

M = 6

M1 = 4- 9/16

N = 2- 3/16

R = 1

**Min Hole
Size** = 4-5/8

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

