

Part No: 8171V-040SR

Schedule 80 PVC & CPVC

Tank Adapter

Desc: 4 PVC TANK ADAPTR SOCXSRFPT FKM GASKET

MSRP: 1143.24

Part Code: 100

Weight(lbs): 3.519

Weight(kg): 1.596

Weight(gm): 1596


Size: 4"

Color: GRAY

Material: PVC

Connection Socket x SR Fipt (New Style)

Gasket FKM

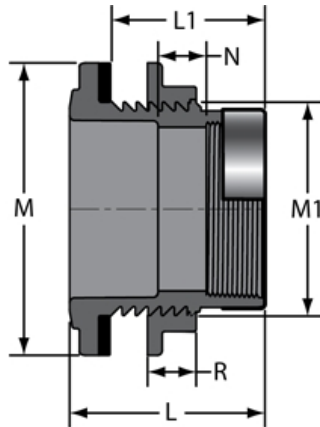

L = 5

L1 = 4

M = 7-7/16

M1 = 5-7/16

N = 1- 1/4

R = 1- 1/4

**Min Hole
Size** = 5-1/2

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

