

Part No: 8171V-060CSR

Schedule 80 PVC & CPVC

Tank Adapter

Desc: 6 CPVC TANK ADAPTER SOCXSRFPT FKM GSKT

MSRP: 3028.46

Part Code: 101

Weight(lbs): 9.288

Weight(kg): 4.213

Weight(gm): 4213


Size: 6"

Color: GRAY

Material: CPVC

Connection Socket x SR Fipt (New Style)

Gasket FKM

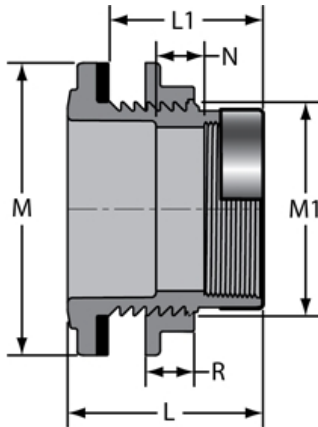

Min Hole Size = 8

M1 = 7-11/16

N = 1/16

R = 1- 1/4

L = 4-31/32

L1 = 4- 1/16

M = 10- 1/16

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

