

Part No: 8172-003CSR

Schedule 80 PVC & CPVC

Tank Adapter

Desc: 3/8 CPVC TANK ADPT FPTXSRFPT W/NPRN GSKT

MSRP: 110.79

Part Code: 101

Weight(lbs): 0.139

Weight(kg): 0.063

Weight(gm): 63


Size: 3/8"

Color: GRAY

Material: CPVC

Connection Fipt x SR Fipt (New Style)

Gasket Neoprene

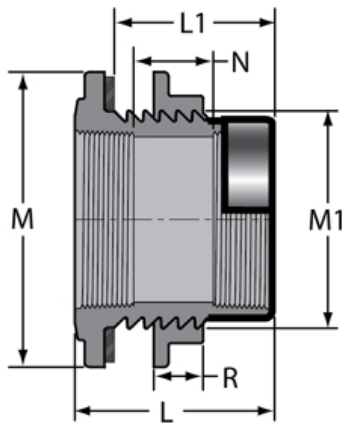

L = 2-17/32

L1 = 1-27/32

M = 1-21/32

M1 = 1-5/32

N = 1-3/8

R = 1/2

Min Hole Size = 1-3/16

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

