

Part No: 8172-007CSR

Schedule 80 PVC & CPVC

Tank Adapter

Desc: 3/4 CPVC TANK ADPTER FPTXSRFPT NPRN GSKT

MSRP: 128.66

Part Code: 101

Weight(lbs): 0.278

Weight(kg): 0.126

Weight(gm): 126


Size: 3/4"

Color: GRAY

Material: CPVC

Connection Fipt x SR Fipt (New Style)

Gasket Neoprene

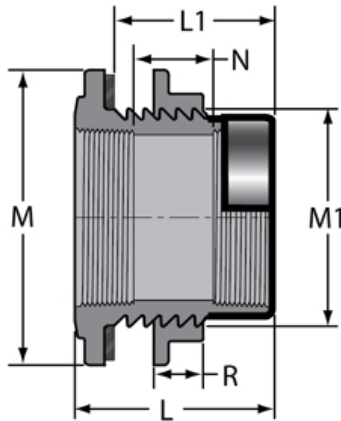

L = 2-15/16

L1 = 2-7/32

M = 2- 1/4

M1 = 1- 5/8

N = 1-1/2

R = 5/8

Min Hole Size = 1-3/4

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

