

**Part No:** 8172-015C

**Schedule 80 PVC & CPVC**

**Tank Adapter**

**Desc:** 1-1/2 CPVC TANK ADAPT FPTXFPT NPRN GASKT

**MSRP:** 211.26

**Part Code:** 101

**Weight(lbs):** 0.743

**Weight(kg):** 0.337

**Weight(gm):** 337


**Size:** 1-1/2"

**Color:** GRAY

**Material:** CPVC

**Connection** Fipt x Fipt (New Style)

**Gasket** Neoprene

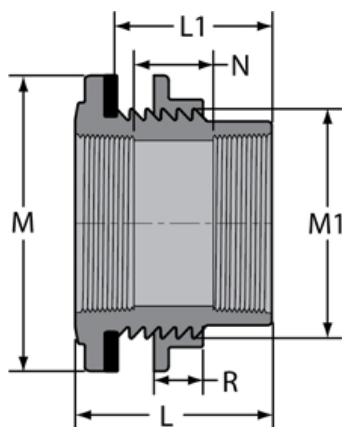

**L** = 3-5/8

**L1** = 2-13/16

**M** = 3-5/8

**M1** = 2-11/16

**N** = 1-23/32

**R** = 5/8

**Min Hole Size** = 2-3/4

## Injection Molded Dimension References:

**G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

**H** = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

**J** = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

**L** = Overall length of fittings; ± 1/16 inch.

**M** = Outside diameter of socket/thread hub; ± 1/16 inch.

**N** = Socket bottom to socket bottom; couplings; ± 1/16 inch.

**W** = Height of cap; ± 1/16 inch

## Typical Molded Dimension References

