

**Part No:** 8172-040

**Schedule 80 PVC & CPVC**

**Tank Adapter**

**Desc:** 4 PVC TANK ADAPTER FPTXFPT NPRN GASKET

**MSRP:** 580.46

**Part Code:** 100

**Weight(lbs):** 3.536

**Weight(kg):** 1.604

**Weight(gm):** 1604


**Size:** 4"

**Color:** GRAY

**Material:** PVC

**Connection** Fipt x Fipt (New Style)

**Gasket** Neoprene

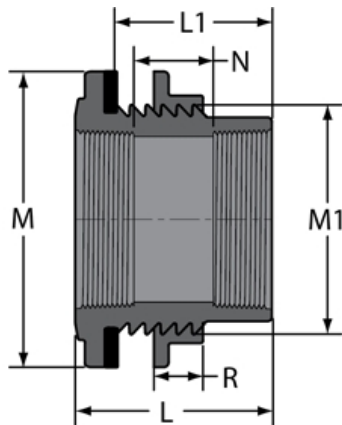

**L** = 4-31/32

**L1** = 3-15/16

**M** = 7-7/16

**M1** = 5-7/16

**N** = 2

**R** = 1- 1/4

**Min Hole  
Size** = 5-1/2

## Injection Molded Dimension References:

**G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

**H** = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

**J** = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

**L** = Overall length of fittings; ± 1/16 inch.

**M** = Outside diameter of socket/thread hub; ± 1/16 inch.

**N** = Socket bottom to socket bottom; couplings; ± 1/16 inch.

**W** = Height of cap; ± 1/16 inch

## Typical Molded Dimension References

