

Part No: 8172-060C

Schedule 80 PVC & CPVC

Tank Adapter

Desc: 6 CPVC TANK ADAPTER FPTXFPT NPRN GASKET

MSRP: 1935.99

Part Code: 101

Weight(lbs): 6.224

Weight(kg): 2.823

Weight(gm): 2823


Size: 6"

Color: GRAY

Material: CPVC

Connection Fipt x Fipt (New Style)

Gasket Neoprene

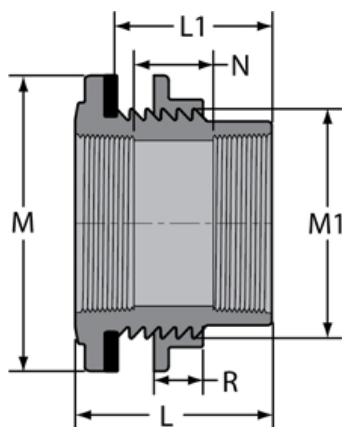

L = 5

L1 = 4

M = 10-3/32

M1 = 8

N = 1-1/8

R = 1- 1/4

**Min Hole
Size** = 8

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

