

Part No: 8172E-005CSR

Schedule 80 PVC & CPVC

Tank Adapter

Desc: 1/2 CPVC TANK ADAPT FPTXSRFPT EPDM GASKT

MSRP: 115.13

Part Code: 101

Weight(lbs): 0.258

Weight(kg): 0.117

Weight(gm): 117


Size: 1/2"

Color: GRAY

Material: CPVC

Connection Fipt x SR Fipt (New Style)

Gasket EPDM

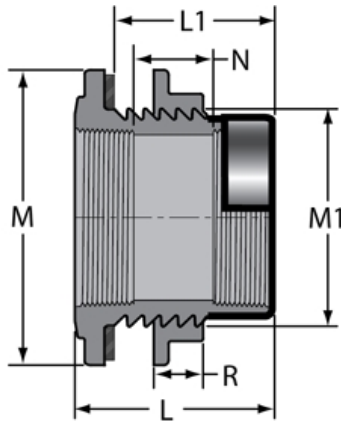

L = 2-15/16

L1 = 2-3/16

Min Hole Size = 1-1/2

M = 2- 1/16

M1 = 1-15/32

N = 1-1/2

R = 5/8

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

