

Part No: 8172E-012C

Schedule 80 PVC & CPVC

Tank Adapter

Desc: 1-1/4 CPVC TANK ADAPT FPTXFPT EPDM GASKT

MSRP: 201.04

Part Code: 101

Weight(lbs): 0.542

Weight(kg): 0.246

Weight(gm): 246


Size: 1-1/4"

Color: GRAY

Material: CPVC

Connection Fipt x Fipt (New Style)

Gasket EPDM

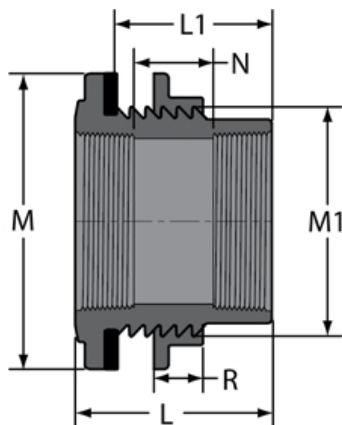

L = 3-13/32

L1 = 2-5/8

M = 3-1/8

M1 = 2-5/16

Min Hole Size = 2-3/8

N = 1-17/32

R = 5/8

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

