

Part No: 8172E-020CSR

Schedule 80 PVC & CPVC

Tank Adapter

Desc: 2 CPVC TANK ADAPTER FPTXSRFPT EPDM GSKET

MSRP: 298.07

Part Code: 101

Weight(lbs): 1.429

Weight(kg): 0.648

Weight(gm): 648


Size: 2"

Color: GRAY

Material: CPVC

Connection Fipt x SR Fipt (New Style)

Gasket EPDM

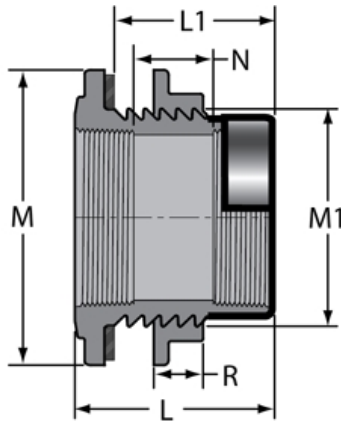

L = 4- 1/8

L1 = 3- 1/4

M = 4-7/8

M1 = 3-1/4

N = 2-5/32

R = 3/4

**Min Hole
Size** = 3-3/8

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

