

Part No: 8172E-025C

Schedule 80 PVC & CPVC

Tank Adapter

Desc: 2-1/2 CPVC TANK ADAPT FPTXFPT EPDM GASKT

MSRP: 416.88

Part Code: 101

Weight(lbs): 2.169

Weight(kg): 0.984

Weight(gm): 984


Size: 2-1/2"

Color: GRAY

Material: CPVC

Connection Fipt x Fipt (New Style)

Gasket EPDM

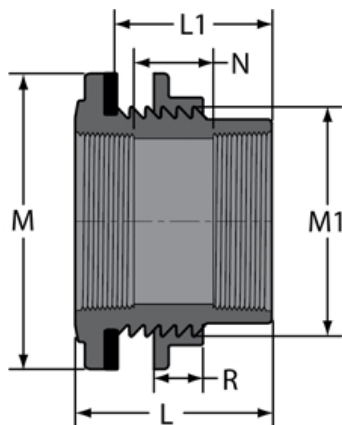

L = 4-27/32

L1 = 3-29/32

M = 5- 1/4

M1 = 3-13/16

N = 2-7/32

R = 1

**Min Hole
Size** = 3-7/8

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

