

**Part No:** 8172E-060CSR

**Schedule 80 PVC & CPVC**

**Tank Adapter**

**Desc:** 6 CPVC TANK ADAPTER FPTXFPT EPDM GASKET

**MSRP:** 2004.22

**Part Code:** 101

**Weight(lbs):** 9.44

**Weight(kg):** 4.282

**Weight(gm):** 4282


**Size:** 6"

**Color:** GRAY

**Material:** CPVC

**Connection** Fipt x SR Fipt (New Style)

**Gasket** EPDM

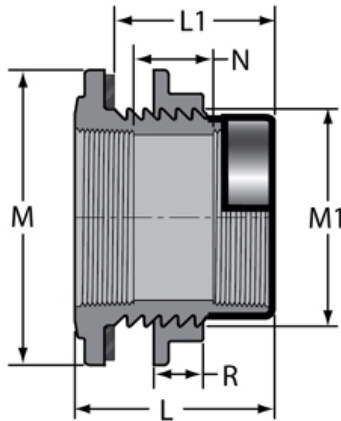

**L** = 5

**L1** = 4-3/32

**M** = 9-15/16

**M1** = 8

**N** = 1-1/8

**R** = 1-1/4

**Min Hole  
Size** = 8

## Injection Molded Dimension References:

**G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

**H** = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

**J** = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

**L** = Overall length of fittings; ± 1/16 inch.

**M** = Outside diameter of socket/thread hub; ± 1/16 inch.

**N** = Socket bottom to socket bottom; couplings; ± 1/16 inch.

**W** = Height of cap; ± 1/16 inch

## Typical Molded Dimension References

