

Part No: 8172V-005C

Schedule 80 PVC & CPVC

Tank Adapter

Desc: 1/2 CPVC TANK ADAPTER FPTXFPT FKM GASKET

MSRP: 174.31

Part Code: 101

Weight(lbs): 0.254

Weight(kg): 0.115

Weight(gm): 115


Size: 1/2"

Color: GRAY

Material: CPVC

Connection Fipt x Fipt (New Style)

Gasket FKM

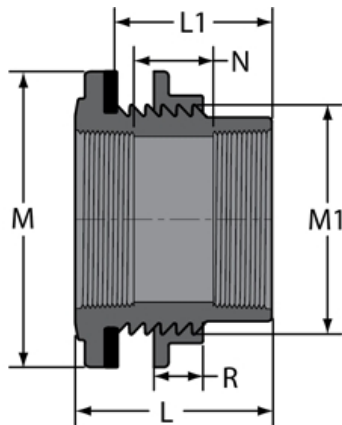

L = 2-29/32

L1 = 2-3/16

M = 2-1/16

M1 = 1-7/16

N = 1-15/32

R = 5/8

Min Hole Size = 1-1/2

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

