

Part No: 8172V-012CSR

Schedule 80 PVC & CPVC

Tank Adapter

Desc: 1-1/4 CPVC TANK ADAPT FPTXSRFPT FKM GSKT

MSRP: 285.18

Part Code: 101

Weight(lbs): 0.569

Weight(kg): 0.258

Weight(gm): 258


Size: 1-1/4"

Color: GRAY

Material: CPVC

Connection Fipt x SR Fipt (New Style)

Gasket FKM

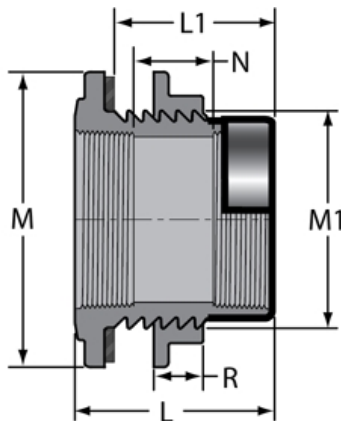

L = 3-9/16

L1 = 2-21/32

M = 3-1/8

M1 = 2- 5/16

N = 1-9/16

R = 5/8

**Min Hole
Size** = 2-3/8

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

