

Part No: 8172V-060CSR

Schedule 80 PVC & CPVC

Tank Adapter

Desc: 6 CPVC TANK ADAPT FPTXSRFPT FKM GASKET

MSRP: 3678.96

Part Code: 101

Weight(lbs): 9.588

Weight(kg): 4.349

Weight(gm): 4349


Size: 6"

Color: GRAY

Material: CPVC

Connection Fipt x SR Fipt (New Style)

Gasket FKM

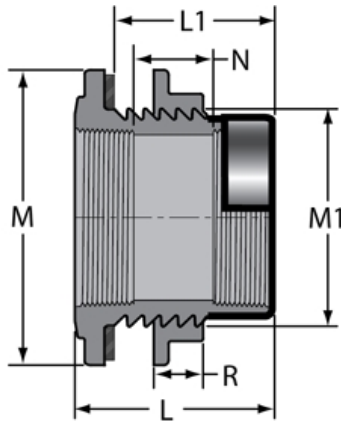

R = 1-1/4 Min Hole Size = 8 L = 5 L1 = 4-3/32 M = 9-15/16
M1 = 8 N = 1-1/8

Injection Molded Dimension References:

- G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.
- H** = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.
- J** = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch
- L** = Overall length of fittings; ± 1/16 inch.
- M** = Outside diameter of socket/thread hub; ± 1/16 inch.
- N** = Socket bottom to socket bottom; couplings; ± 1/16 inch.
- W** = Height of cap; ± 1/16 inch

Typical Molded Dimension References

