

Part No: 818-120F

Fabricated Fittings

Elbow

Desc: 12 PVC 15 ELL SOC SCH80 FAB

MSRP: 744.54

Part Code: 083

Weight(lbs): 26.098


Weight(kg): 11.838

Weight(gm): 11838

Size: 12"

Color: GRAY

Material: PVC

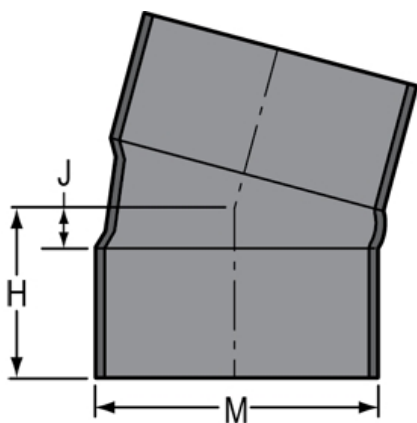

Schedule SCH 80

Angle 15 Degree

Connection Socket X Socket

Type Standard

H = 8- 1/16

J = 1-13/16

M = 14- 1/8

Fabricated Dimension References:

- G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.
- H** = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.
- J** = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.
- L** = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.
- M** = Outside diameter of socket/thread hub; $\pm 1/4$ inch.
- N** = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.
- W** = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

