

Part No: 819-040

Schedule 80 PVC & CPVC

Elbow

Desc: 4 PVC 45 ELL FPT SCH80

MSRP: 361.1

Part Code: 080

Weight(lbs): 2.712

Weight(kg): 1.23

Weight(gm): 1230

Size: 4"


Color: GRAY

Material: PVC

Connection Fipt x Fipt

Angle 45°

Type Standard

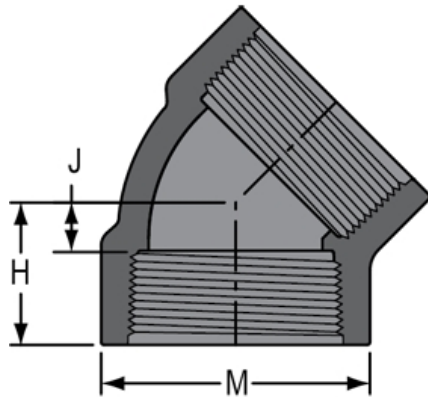

H = 3- 1/4

J = 1-3/4

M = 5- 1/4

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

