

Part No: 820-751CF

Fabricated Fittings

Cross

Desc: 16X2 CPVC RED CROSS SOC SCH80

MSRP: 6756.3

Part Code: 097

Weight(lbs): 77.748

Weight(kg): 35.266

Weight(gm): 35266

Size: 16"X16"X2"X2"


Color: GRAY

Material: CPVC

Schedule SCH 80

Connection Socket X Socket

Type Reduction

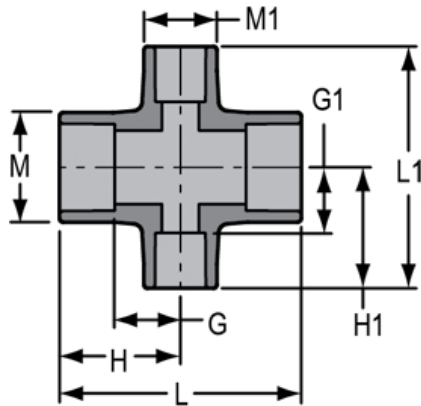

G = 5- 7/8

G1 = 9- 1/2

H = 13- 7/8

H1 = 11- 1/4

L = 27- 3/4

L1 = 22- 1/2

M = 17-11/16

M1 = 2-13/16

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

