

Part No: 824-030CF

Fabricated Fittings

Elbow

Desc: 3 CPVC 60 ELL SOC SCH80

MSRP: 485.01

Part Code: 097

Weight(lbs): 1.521

Weight(kg): 0.69

Weight(gm): 690

Size: 3"

Color: GRAY


Material: CPVC

Schedule SCH 80

Angle 60 Degree

Connection Socket X Socket

Type Standard

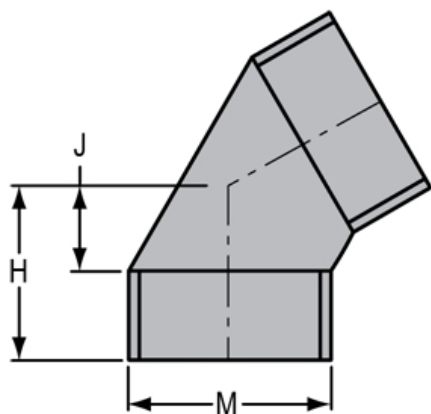

H = 4

J = 1-3/4

M = 4-1/8

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

