

Part No: 824-060F

Fabricated Fittings

Elbow

Desc: 6 PVC 60 ELL SOC SCH80 FAB

MSRP: 598.9

Part Code: 083

Weight(lbs): 5.864

Weight(kg): 2.66

Weight(gm): 2660

Size: 6"

Color: GRAY


Material: PVC

Schedule SCH 80

Angle 60 Degree

Connection Socket X Socket

Type Standard

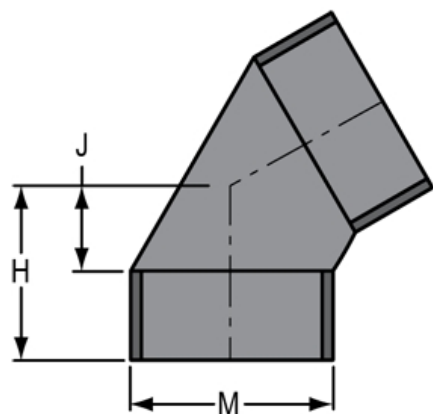

M = 7- 1/2

H = 6- 1/8

J = 2- 7/8

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/4 & larger ± 1/2 inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; ± 1/4 inch.; wyes ± 1/2 inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/4 inch; 14" & larger ± 1/2 inch.

L = Overall length of fittings; ± 1/2 inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; ± 1/4 inch.

N = Socket bottom to socket bottom; couplings; ± 1/2 inch.

W = Height of cap; ± 1/4 inch.

Typical Fabricated Dimension References

