

Part No: 824-140CF

Fabricated Fittings

Elbow

Desc: 14 CPVC 60 ELL SOC SCH80

MSRP: 9183.44

Part Code: 097

Weight(lbs): 88.976

Weight(kg): 40.359

Weight(gm): 40359

Size: 14"

Color: GRAY


Material: CPVC

Schedule SCH 80

Angle 60 Degree

Connection Socket X Socket

Type Standard

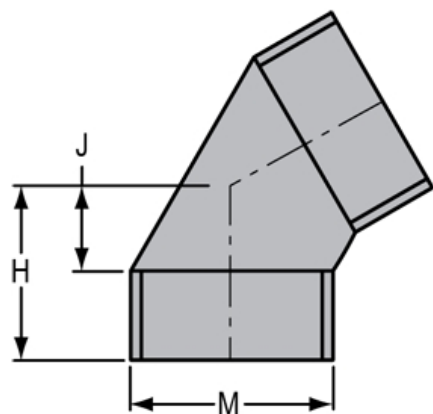

H = 12-15/16

J = 5-15/16

M = 15- 1/2

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

