

Part No: 826-005X12C

Schedule 80 PVC & CPVC

Expansion Joint

Desc: 1/2 CPVC EXPAN JOINT SOCX12 FKM

MSRP: 662.04

Part Code: 085

Weight(lbs): 1.043

Weight(kg): 0.473

Weight(gm): 473

Size: 1/2"


Color: GRAY

Material: CPVC

Connection Fabricated Socket

Travel Length 12" Travel

NOTE T = TRAVEL

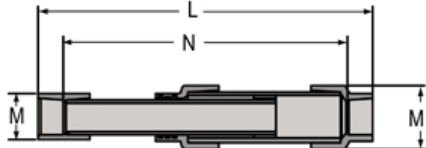

T = 12

L- = 16-9/16
CLOSED

M = 1-3/16

L-OPEN = 28-9/16

N-OPEN = 26-13/16

M1 = 1-3/4

N- = 14-13/16
CLOSED

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

