

Part No: 826-007X6C

Schedule 80 PVC & CPVC

Expansion Joint

Desc: 3/4 CPVC EXPAN JOINT SOCX6 FKM

MSRP: 711.32

Part Code: 085

Weight(lbs): 1.076

Weight(kg): 0.488

Weight(gm): 488

Size: 3/4"


Color: GRAY

Material: CPVC

Connection Fabricated Socket

Travel Length 6" Travel

NOTE T = TRAVEL

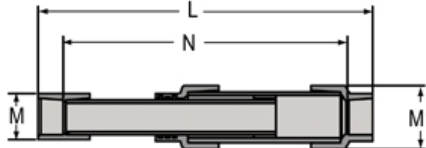

T = 6

L_C = 12
CLOSED

M = 1-7/16

M1 = 2-1/8

N_C = 10
CLOSED

L-OPEN = 18

N-OPEN = 16

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/4 & larger ± 1/2 inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; ± 1/4 inch.; wyes ± 1/2 inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/4 inch; 14" & larger ± 1/2 inch.

L = Overall length of fittings; ± 1/2 inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; ± 1/4 inch.

N = Socket bottom to socket bottom; couplings; ± 1/2 inch.

W = Height of cap; ± 1/4 inch.

Typical Fabricated Dimension References

