

Part No: 826-012X12C

Schedule 80 PVC & CPVC

Expansion Joint

Desc: 1-1/4 CPVC EXPAN JNT SOCX12 FKM

MSRP: 906.51

Part Code: 085

Weight(lbs): 2.233

Weight(kg): 1.013

Weight(gm): 1013

Size: 1-1/4"


Color: GRAY

Material: CPVC

Connection Fabricated Socket

Travel Length 12" Travel

NOTE T = TRAVEL

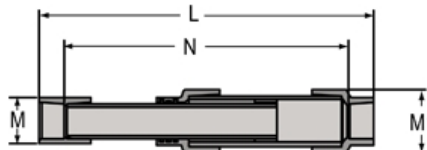

T = 12

L_{CLOSED} = 19-1/16

M = 2-1/4

M1 = 2-3/8

N_{CLOSED} = 16-1/2

L_{OPEN} = 31-1/16

N_{OPEN} = 28-1/2

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/4 & larger ± 1/2 inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; ± 1/4 inch.; wyes ± 1/2 inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/4 inch; 14" & larger ± 1/2 inch.

L = Overall length of fittings; ± 1/2 inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; ± 1/4 inch.

N = Socket bottom to socket bottom; couplings; ± 1/2 inch.

W = Height of cap; ± 1/4 inch.

Typical Fabricated Dimension References

