

Part No: 826-012X6C

Schedule 80 PVC & CPVC

Expansion Joint

Desc: 1-1/4 CPVC EXPAN JOINT SOCX6 FKM

MSRP: 807.57

Part Code: 085

Weight(lbs): 1.609

Weight(kg): 0.73

Weight(gm): 730

Size: 1-1/4"


Color: GRAY

Material: CPVC

Connection Fabricated Socket

Travel Length 6" Travel

NOTE T = TRAVEL

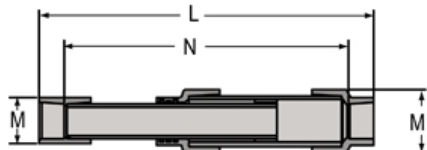

T = 6

L_C = 13-1/16
CLOSED

M = 2-1/4

M1 = 2-3/8

N_C = 10-1/2
CLOSED

L_{OPEN} = 19-1/16

N_{OPEN} = 16-1/2

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/4 & larger ± 1/2 inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; ± 1/4 inch.; wyes ± 1/2 inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/4 inch; 14" & larger ± 1/2 inch.

L = Overall length of fittings; ± 1/2 inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; ± 1/4 inch.

N = Socket bottom to socket bottom; couplings; ± 1/2 inch.

W = Height of cap; ± 1/4 inch.

Typical Fabricated Dimension References

